


3050 Spruce Street, Saint Louis, MO 63103, USA

Website: www.sigmaaldrich.comEmail USA: techserv@sial.comOutside USA: eurtechserv@sial.com

Product Specification

Product Name:
4-Hydroxyestrone - ≥90% (HPLC)

Product Number: **H6012**
CAS Number: 3131-23-5
MDL: MFCD00079358
Formula: C₁₈H₂₂O₃
Formula Weight: 286.37 g/mol
Storage Temperature: -20 °C

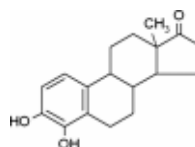

TEST	Specification
------	---------------

Appearance (Color)	White to Yellow to Beige and Faint Brown to Light Brown
Appearance (Form)	Powder
Solubility (Color)	Colorless to Yellow to Brown-Yellow and Very Faint Brown to Light Brown
Solubility (Turbidity)	Clear to Very Slightly Hazy
10 mg/mL, MeOH	
EMM	2.10 - 2.50
Lambda max 280 to 281 nm in EtOH	
Purity (HPLC)	≥ 90 %

Specification: PRD.1.ZQ5.10000023549

Sigma-Aldrich warrants, that at the time of the quality release or subsequent retest date this product conformed to the information contained in this publication. The current Specification sheet may be available at Sigma-Aldrich.com. For further inquiries, please contact Technical Service. Purchaser must determine the suitability of the product for its particular use. See reverse side of invoice or packing slip for additional terms and conditions of sale.