

3050 Spruce Street, Saint Louis, MO 63103, USA

Website: [www.sigmaaldrich.com](http://www.sigmaaldrich.com)Email USA: [techserv@sial.com](mailto:techserv@sial.com)Outside USA: [eurtechserv@sial.com](mailto:eurtechserv@sial.com)

## Product Specification

Product Name:

 $\beta$ -Nicotinamide adenine dinucleotide, reduced disodium salt – ~98%, pkg of 10 mg (per vial)

Product Number:

N6785

CAS Number:

606-68-8

MDL:


MFCD00036200

Formula:

C<sub>21</sub>H<sub>27</sub>N<sub>7</sub>Na<sub>2</sub>O<sub>14</sub>P<sub>2</sub>

Formula Weight:

709.4 g/mol

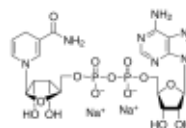

TEST	Specification
Appearance (Color)	White to Light Yellow
Appearance (Form)	Powder
Solubility (Color)	Colorless
10 mg plus 10 ml 0.01 N NaOH	
Solubility (Turbidity)	Clear
10 mg plus 10 ml 0.01 N NaOH	
Solubility (Form)	Solution
10 mg plus 10 ml 0.01 N NaOH	
mg/vial	10 - 12
Suitability	Suitable
Suitable for use as a co-factor in enzymatic assays.	

Specification: PRD.1.ZQ5.10000006453

Sigma-Aldrich warrants, that at the time of the quality release or subsequent retest date this product conformed to the information contained in this publication. The current Specification sheet may be available at [Sigma-Aldrich.com](http://Sigma-Aldrich.com). For further inquiries, please contact Technical Service. Purchaser must determine the suitability of the product for its particular use. See reverse side of invoice or packing slip for additional terms and conditions of sale.