


3050 Spruce Street, Saint Louis, MO 63103, USA

Website: [www.sigmaaldrich.com](http://www.sigmaaldrich.com)Email USA: [techserv@sial.com](mailto:techserv@sial.com)Outside USA: [eurtechserv@sial.com](mailto:eurtechserv@sial.com)

## Product Specification

Product Name:  
Fumitremorgin C – from *Neosartorya fischeri*, >98% (HPLC and TLC), film

Product Number: **F9054**  
CAS Number: 118974-02-0  
Formula: C<sub>22</sub>H<sub>25</sub>N<sub>3</sub>O<sub>3</sub>  
Formula Weight: 379.45 g/mol  
Storage Temperature: 2 - 8 °C

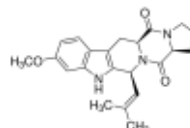

TEST	Specification
------	---------------

Appearance (Form)	Conforms
Film (Dried In Situ)	
Solubility (Solvent)	Acetonitrile
Solubility (Conc)	0.90 - 1.10 mg/ml
Solubility (Turbidity)	Clear
Solubility (Color)	Colorless to Faint Yellow
Purity (HPLC)	≥ 98.00 %
Vial Content (Actual Content)	0.250 - 0.300
Vial Content (Size)	0.25 - 0.25
Vial Content (Unit Of Measure)	mg
Vial Content (Overpack)	≤ 20.00 %
Recommended Retest Period	-----
3Years	

Specification: PRE.2.ZQ5.10000001864

Sigma-Aldrich warrants, that at the time of the quality release or subsequent retest date this product conformed to the information contained in this publication. The current Specification sheet may be available at [Sigma-Aldrich.com](http://Sigma-Aldrich.com). For further inquiries, please contact Technical Service. Purchaser must determine the suitability of the product for its particular use. See reverse side of invoice or packing slip for additional terms and conditions of sale.