

3050 Spruce Street, Saint Louis, MO 63103, USA

Website: www.sigmaaldrich.com

Email USA: techserv@sial.com

Outside USA: eurtechserv@sial.com

## Product Specification


Product Name:  
PK 11195

Product Number:  
CAS Number:

**C0424**  
85532-75-8

Formula:  
Formula Weight:

C<sub>21</sub>H<sub>21</sub>ClN<sub>2</sub>O  
352.86 g/mol

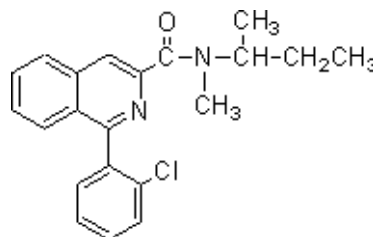

### TEST

### Specification

Appearance (Form)	Powder
Appearance (Colour)	White to White w/ Yellow Cast
Solubility (Solvent)	Chloroform
Solubility (Conc)	9.80 - 10.20 mg/ml
Solubility (Turbidity)	Clear
Solubility (Color)	Colorless to Faint Yellow
Elemental Anal. (%C anhydrous)	71.00 - 71.80 %
Elemental Anal. (%N anhydrous)	7.63 - 8.23 %
Purity (TLC)	≥ 98.00 %
NMR (Solvent)	CDCl <sub>3</sub>
Identity by NMR	Consistent
NMR (Residual Solvent 1)	Ethylacetate
NMR (% Solvent 1)	≤ 1.00 %
NMR (Residual Solvent 2)	Isopropyl Ether
NMR (% Solvent 2)	≤ 1.00 %
NMR (Total % Resid.Solvents)	≤ 1.00 %
Recommended Retest Period	-----
3 Years	

Specification: PRE.0.ZQ5.10000001514

Sigma-Aldrich warrants, that at the time of the quality release or subsequent retest date this product conformed to the information contained in this publication. The current Specification sheet may be available at Sigma-Aldrich.com. For further inquiries, please contact Technical Service. Purchaser must determine the suitability of the product for its particular use. See reverse side of invoice or packing slip for additional terms and conditions of sale.