

3050 Spruce Street, Saint Louis, MO 63103, USA

Website: [www.sigmaldrich.com](http://www.sigmaldrich.com)Email USA: [techserv@sial.com](mailto:techserv@sial.com)Outside USA: [eurtechserv@sial.com](mailto:eurtechserv@sial.com)


## Product Specification

Product Name:

Kanamycin solution from *Streptomyces kanamyceticus* - 50 mg/mL in 0.9% NaCl, BioReagent, liquid, sterile-filtered, suitable for cell culture

Product Number:

K0254

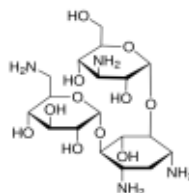

Storage Temperature:

2 - 8 °C

TEST	Specification
Appearance (Turbidity)	Clear
Appearance (Form)	Solution
Osmolality	≤ 500 mOs/kg
Potency	50 - 60 mg/ml
Sterility	Pass
Endotoxin Level at 2ml/L	≤ 0.5 EU/ml
Cell Culture Test of control	≥ 50 %
Cell Line	Attached Cell Line
Expiration Date Period 24 months	-----

Specification: PRD.0.ZQ5.10000051132

Sigma-Aldrich warrants, that at the time of the quality release or subsequent retest date this product conformed to the information contained in this publication. The current Specification sheet may be available at [Sigma-Aldrich.com](http://Sigma-Aldrich.com). For further inquiries, please contact Technical Service. Purchaser must determine the suitability of the product for its particular use. See reverse side of invoice or packing slip for additional terms and conditions of sale.